 



# DUO cable

## NEDU-L2R1-M8G3-K-1L1-1L2-M8G4

Part number: 574591

**FESTO**

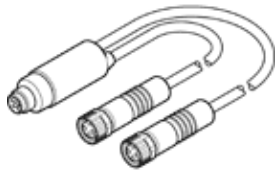

### Data sheet

Feature	Value
Operating voltage range AC	0 ... 60 V
Surge strength	1.5 kV
Acceptable current load at 40°C	2 A
Corrosion resistance classification CRC	1
Protection class	IP67
Ambient temperature	-25 ... 85 °C
Electrical connection 1	Straight plug, M8x1, 4-pin
Electrical connection 2	Straight socket, 2xM8, 3-pin
Cable diameter	3.1 mm
Cable length	1 m
Materials note	Conforms to RoHS
Material information, socket	PUR
Material information, housing	PUR
Material information for crimp connectors	Brass Gold plated