


T distributor FCK-3-PK-6-KU

Part number: 6275

FESTO

Polymeric design.

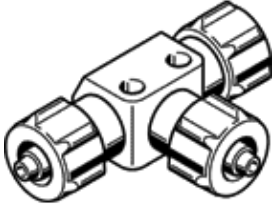

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 5.3 mm |
| Assembly position | Any |
| Design | T-shaped |
| Container size | 10 |
| Operating pressure for entire temperature range | -0.095 ... 1 MPa |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Operating pressure for entire temperature range | -13.775 ... 145 psi |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 60 °C |
| Pneumatic connection, port 1 | For tubing outside diameter 8 mm for barbed connector internal diameter 6 mm with nut |
| Pneumatic connection, port 2 | For tubing outside diameter 8 mm for barbed connector internal diameter 6 mm with nut |
| Material of union nut | POM |
| Materials note | Conforms to RoHS |
| Material – connector | POM |