 



PE converter PE-PK-4

Part number: 7470

FESTO

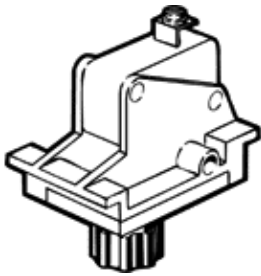

Data sheet

Feature	Value
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Measured variable	Relative pressure
Measurement method	Pneu./elect. pressure transducer
Working pressure	0 ... 0.25 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	0 ... 60 °C
Ambient temperature	0 ... 60 °C
Switching element function	Changeover switch
Switch-on point	0.25 bar
Switch-off point	0.07 bar
Max. switching frequency	1 Hz
Minimum load current	100 mA
Operating voltage range AC	12 ... 250 V
Operating voltage range DC	12 ... 250 V
Electrical connection	Screwed terminal
Mounting type	Optional on mounting frame 1n with through hole
Assembly position	Any
Pneumatic connection	PK-4
Materials information, housing	PET POM Steel
Material information, switch contact	silver
Material information, electrical connection	Brass
Materials information for membrane	CR
Protection class	IP00, IP20 with protective cap