


# Flow control VFFG-T-M5-15

Part number: 8025715

FESTO

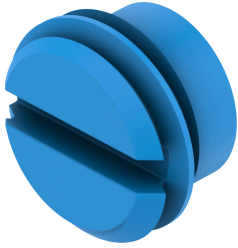

## Data sheet

| Feature  | Value  |
|--|--|
| Valve function                                       | Flow control function  |
| Type of mounting                                     | With thread  |
| Standard nominal flow rate in flow control direction | 67.4 l/min   |
| Operating pressure                                   | -0.9 bar...10 bar  |
| Ambient temperature                                  | -5 °C...60 °C  |
| Nominal width  | 1.55 mm  |
| b-value  | 0.5  |
| C value  | 0.25 l/sbar  |
| Operating medium                                     | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media             | Operation with oil lubrication possible (required for further use) |
| LABS (PWIS) conformity                               | VDMA24364-B1/B2-L  |
| Storage temperature                                  | -20 °C...60 °C   |
| Product weight                                       | 0.5 g  |
| Note on materials                                    | RoHS-compliant   |
| Hollow bolt material                                 | PA   |