


Flow control VFFG-T-M5-A-V1

Part number: 8025716

FESTO

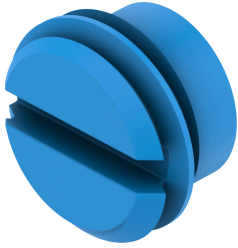

Data sheet

Feature	Value
Valve function	Flow control function
Type of mounting	With thread
Operating pressure	-0.9 bar...10 bar
Ambient temperature	-5 °C...60 °C
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...60 °C
Note on materials	RoHS-compliant
Hollow bolt material	PA