


Supply plate VABF-B10-25-P1A4-G14

Part number: 8026318

FESTO

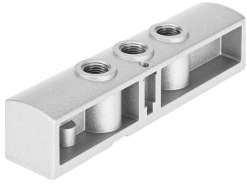

Data sheet

Feature	Value
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	3 Nm
Product weight	110 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Supply plate material	Die-cast aluminum