 



# Vertical pressure supply plate VMPA2-VSP-QS8

Part number: 8029488

FESTO

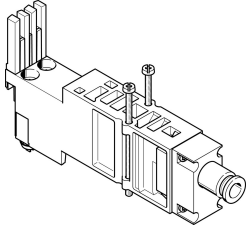

## Data sheet

Feature	Value
Width dimension	21 mm
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	85 g
Pneumatic connection 1	QS-8
Note on materials	RoHS-compliant
Supply plate material	PA-reinforced