


# Sub-base VMPA2-FB-AP-2-1-T0-RV

Part number: 8034550

FESTO

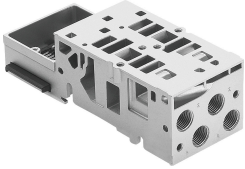

## Data sheet

Feature	Value
Width	52 mm
Length	107.3 mm
Width dimension	21 mm
Max. no. of valve positions	2
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	190 g
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum