


# Coupling plug NPHS-S6-M-G12F

Part number: 8059264

FESTO

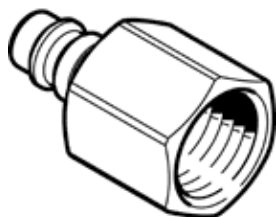

## Data sheet

Feature	Value
Nominal size	7.85 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Product weight	49 g
Pneumatic connection, port 1	Female thread G1/2
Materials note	Conforms to RoHS