


coupling socket NPHS-D6-P-G12

Part number: 8059269

FESTO

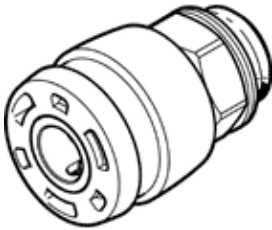

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 11 mm |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Standard nominal flow rate | 1,950 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7::-:] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Ambient temperature | -10 ... 60 °C |
| Nominal tightening torque | 14 Nm |
| Tolerance for nominal tightening torque | ± 20 % |
| Product weight | 113 g |
| Pneumatic connection, port 1 | Male thread G1/2 |
| Materials note | Conforms to RoHS |