


# Axial kit EAMM-A-N80-120GC

Part number: 8063619

FESTO

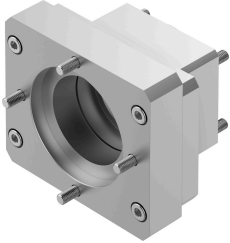

## Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transferable torque	47 Nm
Product weight	2499 g
Interface code, actuator	N80
Interface code, motor in	120GC
Note on materials	RoHS-compliant