


# Manifold strip

## VABM-P6-15MB-G18-M5-4

Part number: 8083544

FESTO

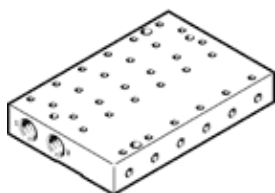

### Data sheet

Feature	Value
Grid dimension	15 mm
Design structure	Connection direction underneath
Max. number of valve positions	4
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Max. tightening torque, valve mounting	0.6 Nm
Product weight	140 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy