


Axial kit EAMM-A-T42-67A

Part number: 8084497

FESTO

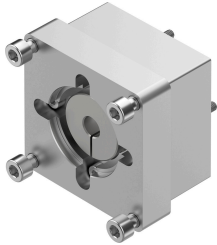

Data sheet

Feature	Value
Nominal length	43 mm
Mounting position	Any
Max. rotational speed	8000 1/min
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	3.2 kgmm ²
Transferable torque	8.5 Nm
Product weight	377 g
Interface code, actuator	T42
Interface code, motor in	67A
Note on materials	RoHS-compliant