


Axial kit EAMM-A-T42-60AB

Part number: 8094949

FESTO

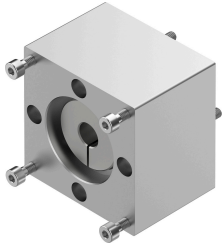

Data sheet

Feature	Value
Nominal length	43 mm
Mounting position	Any
Max. rotational speed	8000 1/min
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	3.2 kgmm ²
Transferable torque	9.5 Nm
Product weight	314 g
Interface code, actuator	T42
Interface code, motor in	60AB
Note on materials	RoHS-compliant