


Axial kit EAMM-A-D19-38AA

Part number: 8105863

FESTO

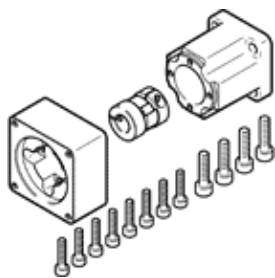

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	1.1 Nm
Product weight	121 g
Interface code, actuator	D19
Interface code, motor in	38AA
Materials note	Conforms to RoHS