


Axial kit

EAMM-A-P5-28B-40R

Part number: 8107711

FESTO

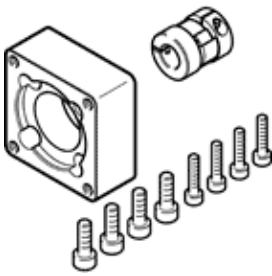

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	1.1 Nm
Product weight	71 g
Interface code, actuator	P5-28B
Interface code, motor in	40R
Materials note	Conforms to RoHS