


# Vertical pressure supply plate VMPA14-VSP-QS3/8

Part number: 8110623

**FESTO**

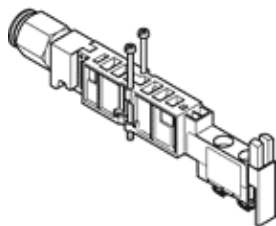

## Data sheet

Feature	Value
Grid dimension	14 mm
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	55 g
Pneumatic connection, port 1	QS-3/8
Materials note	Conforms to RoHS
Material supply plate	PA-reinforced