


# Manifold block-SET VABS-C12-6-S

Part number: 8122790

FESTO

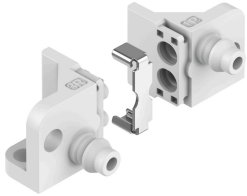

## Data sheet

Feature	Value
Width	13 mm
Mounting position	Any
Structural design	Connection direction at side
Max. no. of valve positions	Versions according to customer specifications possible
Operating pressure	-0.1 MPa...0.7 MPa -1 bar...7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Information on operating and pilot media	Maximum particle size 5 µm
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	5 °C...50 °C
Product weight	3 g
Type of mounting	With through-hole
Pneumatic connection 2	For tubing I.D. 4 mm
Note on materials	RoHS-compliant
Manifold rail material	PBT