


# Coupling EAMC-67-80-25-32-U

Part number: 8134828

FESTO

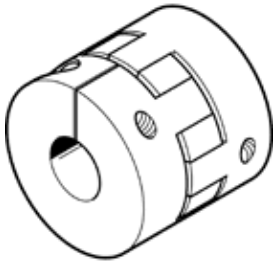

## Data sheet

Feature	Value
Holder diameter 1	25 mm
Holder diameter 2	32 mm
Size	67
Nominal length	80 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	326 kgmm <sup>2</sup>
Transferable torque	150 Nm
Product weight	513 g
Materials note	Conforms to RoHS