


Power supply unit CACN-3A-1-5-G2

Part number: 8149580

FESTO

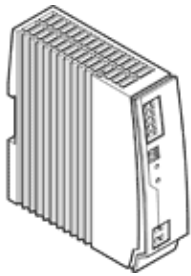

Data sheet

Feature	Value
Width	35 mm
Height	130 mm
Length	115 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	1,1 - 2,2 A
Nominal output voltage DC	24 V
Nominal output current	5 A
Input voltage range AC	100 ... 240 V
Power failure buffering	100 ms
Line frequency	45 ... 65 Hz
Authorization	c UL us - Listed (OL)
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
PWIS conformity	VDMA24364 zone III
Storage temperature	-40 ... 85 °C
Relative air humidity	95 %
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Product weight	450 g
Mounting type	with top-hat rail
Materials note	Conforms to RoHS