


# Coupling

## EAMD-56-56-32-23X27-U

Part number: 8165048

FESTO

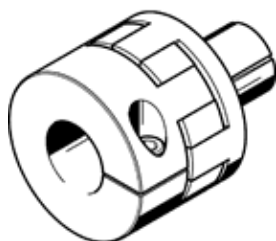

### Data sheet

Feature	Value
Holder diameter 1	32 mm
Holder diameter 2	23 mm
Size	56
Nominal length	56 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	168 kgmm <sup>2</sup>
Transferable torque	75 Nm
Product weight	429 g
Materials note	Conforms to RoHS