


# Bulkhead quick connector SCK-PK-3-KU

Part number: 9387

FESTO

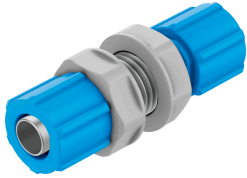

## Data sheet

Feature	Value
Nominal width	2.4 mm
Mounting position	Any
Design	Bulkhead
Pack size	10
Operating pressure for entire temperature range	-0.095 MPa...1 MPa -0.95 bar...10 bar -13.775 psi...145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Pneumatic connection 1	for pneumatic tubing outside diameter 4 mm For barbed fitting, inside diameter 3 mm, with union nut
Pneumatic connection 2	for pneumatic tubing outside diameter 4 mm for barbed fitting, inside diameter 3 mm, with nut
Material of union nut	POM
Note on materials	RoHS-compliant
Nut material	POM
Connector material	POM