


# Vod utičnice KMEB-1-230AC-2.5

Broj artikla: 151690

FESTO

pred ugrađeno, za MEBH-, MOEBH-ventile i N2-magnete.

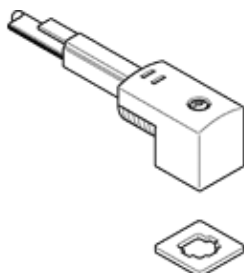

## Tehnički podaci

Svojstvo	Vrijednost
Položaj ugradnje	proizvoljno
Težina proizvoda	125 g
Električni priključak 1	Utičnica, to EN 175301-803, Tip C
Električni spoj 1, dizajn	uglast
Električni spoj 1, tip konektora	Utičnica
Električni spoj 1, kabelski izlaz	Kutni
Electrical connection 1, note about the cable outlet	90°
Električni spoj 1, broj pinova/žica	3
Električni spoj 1, tip ugradnje	na magnetnom ventilu sa središnjim vijkom M2,5
Električni spoj 2, tehnologija spajanja	otvoreni kraj
Električni spoj 2, broj pinova/žica	3
Nazivni pogonski napon AC	230 V
Čvrstoća na udarno naprezanje	4 kV
Priključak zaštitnog vodiča	postoji
Duljina kabla	2,5 m
Svojstvo vodiča	Standard
Promjer kabela	5,2 mm
Struktura kabla	3x0,5
Krajevi žila	Tuljak završetka žile
Mehanička zaštita	IP65 prema IEC 60529
Temperatura okoline	-20 ... 80 °C
CE znak (vidi izjavu o sukladnosti)	prema EU-niski napon-smjernica in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Stupanj onečišćenja	3
Klasa korozione otpornosti KBK	1 - niska otpornost na koroziju
Material cable sheath	PVC
Material housing	PA66-GF30
Material seals	NBR
Material electrical contact	Posrebrana bakrena slitina