


# Utični tuljak NPQH-D-S6-E-P10

Broj artikla: 578318

FESTO

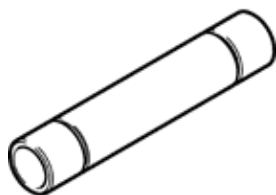

## Tehnički podaci

| Svojstvo  | Vrijednost   |
|---|--|
| Veličina  | Standard   |
| Nazivni promjer                                 | 4 mm   |
| Položaj ugradnje                                | proizvoljno  |
| Oblik   | Ravni oblik  |
| Veličina pakiranja                              | 10   |
| Operating pressure for entire temperature range | -0,095 ... 2 MPa   |
| Pogonski tlak kompletnog temperaturnog područja | -0,95 ... 20 bar   |
| Operating pressure for entire temperature range | -13,775 ... 290 psi  |
| Uputa za pogonski tlak                          | Water: max. 0.6 MPa at 0 - 50 °C   |
| Mjesto izdavanja certifikata                    | NSF C0523185   |
| Pogonski medij                                  | Komprimirani zrak prema ISO 8573-1:2010 [7:-:-]<br>Water (liquid, free of ice)   |
| Uputa o mediju pogona i upravljanja             | Moguć nauljeni pogon   |
| Klasa korozione otpornosti KBK                  | 3 - visoka otpornost na koroziju   |
| PWIS conformity                                 | VDMA24364-B1/B2-L  |
| Klasa čistog prostora                           | This product is a static object, active particle generation is not possible when used correctly.<br>Clean product before using it in a cleanroom environment and ensure it is installed correctly. |
| Sigurnost hrane                                 | Pogledajte izjavu o sukladnosti<br>NSF/ANSI 169  |
| Temperatura okoline                             | 0 ... 150 °C   |
| Težina proizvoda                                | 5,1 g  |
| Pneumatski priključak 1                         | Push-in sleeve diameter 6 mm   |
| Pneumatski priključak 2                         | Push-in sleeve diameter 6 mm   |
| Materijal - napomena                            | RoHS sukladno  |
| Material housing                                | Brass, chemically nickel-plated  |