

 

# Kabelis

## KMPYE-AIF-1-GS-GD-0,3

Gaminio numeris: 170239

FESTO

Surinktas, proporciniam skirstytuvams.

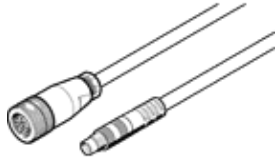

## Tech. Duomenys

Savybės	Reikšmė
Atitinka standartus	EN 61076-2-101
Papildomos funkcijos	Product-specific pin allocation
Cable identification	su priedais
Prijungimo dažnis	500
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with width across flats 18 and longitudinal knurl
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M9x0,5
Electrical connection 2, number of pins/wires	7
Electrical connection 2, occupied pins/wires	6
Electrical connection 2, type of mounting	Screw lock
Nominalus DC įtampos lygis	0 ... 50 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	2 kV
Kabelio ilgis	0,3 m
Kabelio priedas	Suitable for energy chains
Laido bandymo sąlygos	Bandyamas pagal užklausimą
Bending radius, flexible cable installation	≥ 75 mm
Kabelio skersmuo	5,6 mm
Kabelio struktūra	8x0,24 Ekranuotas
Nominalus laidininko skerspjūvis	0,24 mm <sup>2</sup>
Apsaugos klasė	IP65
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 85 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 80 °C
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	1
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	Juodas