


Adaptive Gripper Finger DHAS-GF-80-U-BU

Gaminio numeris: 3998964

FESTO

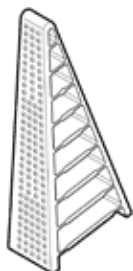

Tech. Duomenys

| Savybės | Reikšmė |
|--------------------------------|--|
| Dydis | 80 |
| Montavimo pozicija | Bet koks |
| Atsparumo korozijai klasė CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| RSBP classification to CD-0033 | F1a |
| Food-safe | See Supplementary material information |
| Aplinkos temperatūra | 10 ... 50 °C |
| Produkto svoris | 13 g |
| Informacija | atitinka RoHS |
| Material clamp jaws | TPE-U(PU) |