 



# Variklio kabelis

## NEBM-SM12G8-E-20-Q5-LE6

Gaminio numeris: 5105619

FESTO

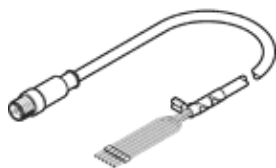

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	6
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	6
Electrical connection 2, occupied pins/wires	6
Nominalus DC įtampos lygis	0 ... 72 V
Nominali darbinė nuolatinė įtampa	24 V
Kabelio ilgis	20 m
Kabelio priedas	Suitable for energy chains
Bending radius, flexible cable installation	≥ 62 mm
Kabelio skersmuo	6,2 mm
Kabelio struktūra	6x0,34 Ekranuotas
Nominalus laidininko skerspjūvis	0,34 mm <sup>2</sup>
Laido galai	Laido antgalis
Apsaugos klasė	IP65
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas