
 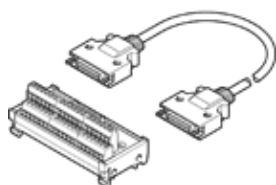


Valdymo linija NEBC-S2G36-K-0.5-N-C2W36-S7

Gaminio numeris: 5105646

FESTO



Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	SCSI
Electrical connection 1, number of pins/wires	36
Electrical connection 1, occupied pins/wires	36
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Galinė juosta
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	Įsuktas terminalas
Electrical connection 2, number of pins/wires	36
Electrical connection 2, occupied pins/wires	36
Electrical connection 2, type of mounting	On H-rail
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	1,5 A
Atsparumas smūgiams	0,5 kV
Kabelio ilgis	0,5 m
Kabelio priedas	Standartas
Bending radius, fixed cable installation	≥ 74 mm
Bending radius, flexible cable installation	≥ 110 mm
Kabelio skersmuo	7,4 mm
Kabelio struktūra	18x2x0,09
Nominalus laidininko skerspjūvis	0,09 mm ²
Apsaugos klasė	IP20
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Informacija	atitinka RoHS
Užterštumo laipsnis	1
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material cable sheath	PVC
Kabelio apvalkalo spalva	Juodas
Material housing	PA PBT
Korpuso spalva	žalias Juodas
Material insulation	PVC