


Pajungimo kabelis KM12-8GD8GS-2-PU

Gaminio numeris: 525617

FESTO

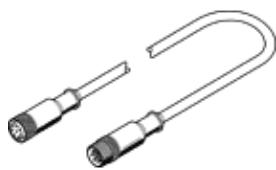

Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Prijungimo dažnis	50
Produkto svoris	140 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukų lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	8
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	8
Electrical connection 2, type of mounting	Screw lock
Nominalus DC įtampos lygis	0 ... 30 V
Nominali darbinė nuolatinė įtampa	30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	2 A
Atsparumas smūgiams	0,8 kV
Kabelio ilgis	2 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandytas pagal užklausimą
Bending radius, fixed cable installation	≥ 32 mm
Bending radius, flexible cable installation	≥ 64 mm
Kabelio skersmuo	6,2 mm
Kabelio skersmens tolerancija	± 0,2 mm
Kabelio struktūra	8x0,25 Ekranuotas
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-25 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	0 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas

Savybės	Reikšmė
Material screw-type lock	Brass, chrome-plated Nickel-plated brass
Material seals	NBR
Material electrical contact	Nickel-plated and gold-plated brass
Material insulation	PP TPE-U(PUR)