

# Kabelis

## KMP6-09P-8-2,5

 

Gaminio numeris: 531184

Classic - nicht für Neukonstruktionen verwenden

Miniaturiniamas vožtuvams, su Sub-D, 9-kontaktų 8 ritėms.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

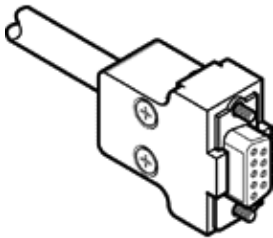

## Tech. Duomenys

| Savybės  | Reikšmė                                     |
|--|---|
| Atitinka standartus  | DIN 41652                                   |
| Cable identification                                       | Without inscription label holder            |
| Prijungimo dažnis  | 50  |
| Produkto svoris  | 248 g                                       |
| Electrical connection 1, function                          | Field device side                           |
| Electrical connection 1, design                            | kampinis                                    |
| Electrical connection 1, connection type                   | Kištuko lizdas                              |
| Electrical connection 1, cable outlet                      | Tiesus                                      |
| Electrical connection 1, connection technology             | Sub-D                                       |
| Electrical connection 1, number of pins/wires              | 9   |
| Electrical connection 1, occupied pins/wires               | 9   |
| Electrical connection 1, type of mounting                  | 2 screws 4-40 UNC                           |
| Electrical connection 2, function                          | Controller side                             |
| Electrical connection 2, connection type                   | Kabelis                                     |
| Electrical connection 2, connection technology             | atviri laidai                               |
| Electrical connection 2, number of pins/wires              | 9   |
| Electrical connection 2, occupied pins/wires               | 9   |
| Nominalus DC įtampos lygis                                 | 0 ... 30 V                                  |
| Nominali darbinė nuolatinė įtampa                          | 24 V  |
| Leistina srovės apkrova prie 40°C                          | 2,8 A                                       |
| Atsparumas smūgiams  | 1 kV  |
| Kabelio ilgis  | 2,5 m                                       |
| Kabelio priedas  | Standartas                                  |
| Laido bandymo sąlygos                                      | Bandymas pagal užklausimą                   |
| Bending radius, fixed cable installation                   | ≥ 76 mm                                     |
| Bending radius, flexible cable installation                | ≥ 114 mm                                    |
| Kabelio skersmuo   | 7,6 mm                                      |
| Kabelio skersmens tolerancija                              | ± 0,25 mm                                   |
| Kabelio struktūra  | 8x0,34+1x0,5                                |
| Nominalus laidininko skerspjuvis                           | 0,34 mm <sup>2</sup><br>0,5 mm <sup>2</sup> |
| Laido galai  | Cut off bluntly                             |
| Apsaugos klasė   | IP40  |
| Note on degree of protection                               | Sumontuotas                                 |
| Aplinkos temperatūra                                       | -25 ... 70 °C                               |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -5 ... 70 °C                                |
| Saugojimo temperatūra                                      | -25 ... 75 °C                               |
| CE ženklas (žr. deklaraciją)                               | in accordance with EU RoHS directive        |
| UKCA marking (see declaration of conformity)               | To UK RoHS instructions                     |
| PWIS conformity  | VDMA24364-B2-L                              |
| Informacija  | atitinka RoHS                               |
| Užterštumo laipsnis  | 2   |

| Savybės                     | Reikšmė                  |
|-----------------------------|--------------------------|
| Material cable sheath       | PVC                      |
| Kabelio apvalkalo spalva    | pilkas                   |
| Material housing            | PBT-sustiprintas         |
| Korpuso spalva              | pilkas                   |
| Material screw-type lock    | Nickel-plated brass      |
| Material electrical contact | Gold-plated copper alloy |