

 

Programavimo kabelis KDI-MC-M8-SUB-9-2,5

Gaminio numeris: 537926
Nebetiekiamas produktas

FESTO

Tinka MTR-DCI-...

Type to be discontinued. Available until 2020. See Support Portal for alternative products.

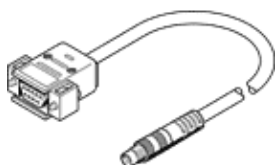

Tech. Duomenys

Savybės	Reikšmė
Protokolas	RS232
Cable identification	su priedais
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M8x1 A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Kištuko lizdas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	8
Electrical connection 2, type of mounting	2x screw 4-40 UNC-2A
Nominalus DC įtampos lygis	0 ... 24 V
Leistina srovės apkrova prie 40°C	4 A
Atsparumas smūgiams	1,5 kV
Kabelio ilgis	2,5 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandytas pagal užklausimą
Kabelio skersmuo	5 mm
Kabelio struktūra	3x0,25 Ekranuotas
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP54
Note on degree of protection	IP40 for Sub-D socket Sumontuotas
Aplinkos temperatūra	0 ... 50 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	0 ... 50 °C
Informacija	Turi PWIS medžiagų atitinka RoHS
Užterštumo laipsnis	2
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	Juodas
Material insulation	PVC