

 

# Maitinimo kabelis KPWR-MC-1-SUB-15HC-10

Gaminio numeris: 538916  
Nebetiekiamas produktas

FESTO

[Logikos ir apkrovos maitinimui prijungti.](#)

Type to be discontinued. Available until 2020. See Support Portal for alternative products.

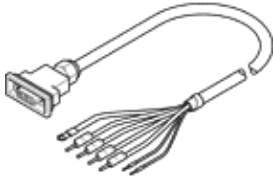

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Sub-D Mixed
Electrical connection 1, number of pins/wires	7
Electrical connection 1, occupied pins/wires	6
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	6
Electrical connection 2, occupied pins/wires	6
Nominalus DC įtampos lygis	0 ... 24 V
Kabelio ilgis	10 m
Kabelio priedas	tinkamas lanksčiai kabelio apsaugai
Bending radius, fixed cable installation	≥ 50 mm
Bending radius, flexible cable installation	≥ 100 mm
Kabelio skersmuo	10 mm
Kabelio struktūra	2x2,5+2x(2x0,34) Ekranuotas
Nominalus laidininko skerspjūvis	0,34 mm <sup>2</sup> 2,5 mm <sup>2</sup>
Laido galai	Pin terminal
Apsaugos klasė	IP54
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	0 ... 40 °C
Aplinkos temperatūra esant lanksčiai kabelių instaliacijai	-25 ... 60 °C
Informacija	Turi PWIS medžiagų
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
Material insulation	TPE-E