 



# Signalo keitiklis SVE4-HS-R-HM8-2P-M8

Gaminio numeris: 544216

FESTO

Pakeičia analoginį jutiklio signalą į valdymo signalus išėjime

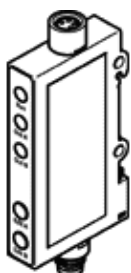

## Tech. Duomenys

Savybės	Reikšmė
Leidimas	RCM Mark c UL us - Listed (OL)
UL-aplinkos temperatūra	-20 ... 60 °C
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvims in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Informacija	atitinka RoHS
Signalu nuotolis	Padėties jutikliui SMH-S1-HG
Aplinkos temperatūra	-20 ... 70 °C
Jungiklio išėjimas	2xPNP
Perjungimo funkcija	Laisvai programuojamas
Komutavimo elemento funkcija	Perjungiamas
Atsparumas trumpam jungimui	Pulsuojantis
Perkrovimo galimybė	Galimas
Nominalus DC įtampos lygis	10 ... 30 V
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, connection type	Kištukas
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	4
Electrical connection 2, type of mounting	Screw lock
Produkto svoris	19 g
Material housing	ABS
Nustatymo pasirinkimai	Teach-In
Apsaugos klasė	IP65
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L