


# Dangtis NECV-S1W37

Gaminio numeris: 545974

FESTO

Skirstytuvų saloms VTSA ir VTSA-F, be kabelio.

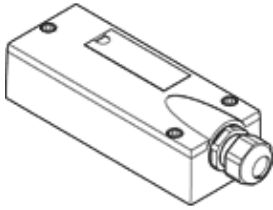

## Tech. Duomenys

Savybės	Reikšmė
Naudojimo sritis	Only for multi-pin plug connection valve terminal VTSA/VTSA-F
Produkto svoris	180 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	37
Electrical connection 1, occupied pins/wires	37
Electrical connection 1, type of mounting	3x M4 screws
Electrical connection 2, connection technology	Crimp contacts
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	2 A
Atsparumas smūgiams	1 kV
Kabelio prijungimas	M20x1,5
Kabelio skersmuo	5 ... 13 mm
Nominalus laidininko skerspjūvis	0,08 ... 0,5 mm <sup>2</sup>
Apsaugos klasė	IP65 NEMA 4
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material housing	PA