


Kištukinės jungtys NECU-FCG40-K

Gaminio numeris: 570895

FESTO

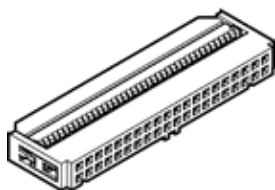

Tech. Duomenys

Savybės	Reikšmė
Atitinka standartus	EN 60603-13
Prijungimo dažnis	50
Cable outlet	Tiesus
Produkto svoris	5 g
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, connection technology	Connection pattern FC
Electrical connection 1, number of pins/wires	40
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, connection technology	Insulation displacement connector
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	1,5 A
Nominalus laidininko skerspjūvis	0,13 mm ²
Nominal conductor cross section (AWG)	AWG26
Apsaugos klasė	IP40
Aplinkos temperatūra	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Informacija	atitinka RoHS
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material housing	PBT-sustiprintas
Material electrical contact	Bronzinis Auksuota