 



Pajungimo kabelis NEBS-L1G4-K-2.5-LE4

Gaminio numeris: 572576

★ Kernprogramm

FESTO

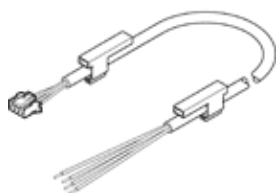

Tech. Duomenys

Savybės	Reikšmė
Cable identification	With inscription label holder
Prijungimo dažnis	100
Produkto svoris	53 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Connection pattern L1J
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	0,8 kV
Kabelio ilgis	2,5 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandymas pagal užklausimą
Bending radius, fixed cable installation	≥ 13 mm
Bending radius, flexible cable installation	≥ 42 mm
Kabelio skersmuo	4,1 mm
Kabelio skersmens tolerancija	± 0,2 mm
Kabelio struktūra	4x0,17
Nominalus laidininko skerspjūvis	0,17 mm ²
Laido galai	Cut off bluntly
Apsaugos klasė	IP40
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-20 ... 60 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 60 °C
Saugojimo temperatūra	-20 ... 60 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Informacija	atitinka RoHS
Užterštumo laipsnis	2
Atsparumo korozijai klasė CRC	4 - Very high corrosion stress
Material cable sheath	PVC
Kabelio apvalkalo spalva	pilkas
Material housing	PA
Korpuso spalva	baltas
Material electrical contact	Tin-plated bronze
Material insulation	PVC