


# Įkišama įvorė NPQH-D-S4-E-P10

Gaminio numeris: 578317

FESTO

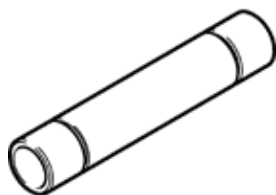

## Tech. Duomenys

Savybės	Reikšmė
Dydis	Standartas
Nominalus dydis	2 mm
Montavimo pozicija	Bet koks
Konstrukcija	Tiesi forma
Dėžės dydis	10
Operating pressure for entire temperature range	-0,095 ... 2 MPa
Darbiis slėgis visam temperatūros diapozonui.	-0,95 ... 20 bar
Operating pressure for entire temperature range	-13,775 ... 290 psi
Nuoroda į darbinį slėgį	Water: max. 0.6 MPa at 0 - 50 °C
Skyriaus sertifikatas	NSF C0523185
Darbinė terpė	Suslėgto oro kokybė pagal ISO8573-1:2010 [7::-] Water (liquid, free of ice)
Reikalavimai darbinei ir valdymo terpei	Galima naudoti oro tepimą
Atsparumo korozijai klasė CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Švaros klasė	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See declaration of conformity NSF/ANSI 169
Aplinkos temperatūra	0 ... 150 °C
Produkto svoris	2,8 g
Pneumatinis pajungimas, portas 1	Push-in sleeve diameter 4 mm
Pneumatinis pajungimas, portas 2	Push-in sleeve diameter 4 mm
Informacija	atitinka RoHS
Material housing	Brass, chemically nickel-plated