
 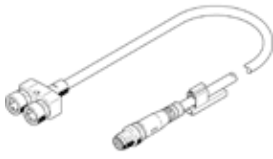


Paskirstytojas

NEDY-L2R1-V1-M8G3-U-M8G4-2.5R

Gaminio numeris: 8005303

FESTO



Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-104
Konstrukcija	Y-distributor with cable on controller side
Distributor type	2 to 1
Cable identification	With inscription label holder
Montavimo tipas	With through-hole for M2 screw su priedais
Produkto svoris	79 g
Electrical connection 1, function	Controller side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 2, function	Field device side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	2x rozetė
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	3 A
Atsparumas smūgiams	0,8 kV
Cable length 1	2,5 m
Kabelio priedas	Suitable for energy chains/robot applications
Laido bandymo sąlygos	Atsparumas lenkimui pagal Festo normas, bandymo sąlygos pagal užklausimą. Bandymas pagal užklausimą Atsparumas sukimui: > 300 000 Zyklen, ±270°/0,1 m Energy chain: > 5 million cycles, bending radius 28 mm
Minimum bending radius with freely moveable use 1	46 mm
Cable diameter 1	4,5 mm
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP65 IP68 IP69K
Aplinkos temperatūra	-25 ... 80 °C
Note on ambient temperature	-10 ... 40 °C when mounted via through-hole
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-20 ... 80 °C
Saugojimo temperatūra	-25 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS

Savybės	Reikšmė
	Be halogeno Free of phosphoric acid ester
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	PC TPE-U(PUR)
Korpuso spalva	Juodas
Material of union nut	Nikeliuotas varis
Material seals	NBR
Material electrical contact	Gold-plated copper alloy
Material threaded sleeve	Nikeliuotas varis