


# surface light SBAL-C6-A-W

Gaminio numeris: 8031158  
Nebetiekiamas produktas

FESTO

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

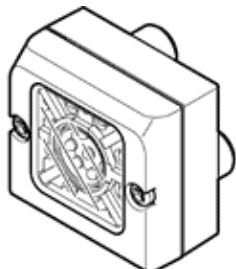

## Tech. Duomenys

| Savybės   | Reikšmė   |
|---|---|
| CE ženklas (žr. deklaraciją)                    | atitinka EU-EMV reikalvumus<br>in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity)    | To UK instructions for EMC<br>To UK RoHS instructions               |
| Leidimas  | RCM Mark  |
| Veikimo nuotolis                                | 100 - 300 mm  |
| Lighting type                                   | Panel light   |
| Šviesos tipas                                   | baltas<br>LED<br>Clear  |
| Wavelength                                      | 410 - 750 nm  |
| Elektrinis pajungimas                           | 12-kontaktų<br>2x M12<br>Kištukas                                   |
| Trigger level                                   | Level 10 V ... UB   |
| Nominali darbinė nuolatinė įtampa               | 24 V  |
| Leistini įtampos svyravimai                     | +/- 10 %  |
| Liekamoji pulsacija                             | 10 %  |
| Current consumption during continuous operation | 80 mA   |
| Current consumption during flash operation      | 200 mA  |
| Maximum number of devices connectable in series | 4   |
| Apsaugotas nuo poliariškumo pakeitimo           | visoms elektrinėms jungtims   |
| Ambient temperature during continuous operation | 0 ... 50 °C   |
| Ambient temperature during flash operation      | 0 ... 50 °C   |
| Saugojimo temperatūra                           | -20 ... 60 °C   |
| Apsaugos klasė                                  | IP67  |
| PWIS conformity                                 | VDMA24364-B2-L  |
| Produkto svoris                                 | 60 g  |
| Montavimo tipas                                 | Fiksuotas "kregždės uodegos" formos griovelyje<br>su priedais       |
| Material housing                                | ABS- sustiprintas   |
| Informacija                                     | atitinka RoHS   |