


# Pajungimo kabelis

## NEBV-Z4WA2L-P-E-2.5-N-M8G3-S1

Gaminio numeris: 8047674

FESTO

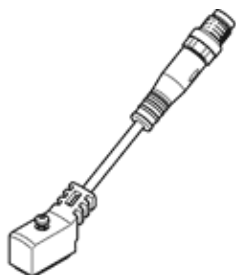

### Tech. Duomenys

Savybės	Reikšmė
Signal status display	LED geltonas
Papildomos funkcijos	Protective circuit
Cable identification	Without inscription label holder
Prijungimo dažnis	50
Produkto svoris	54 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Connection pattern ZC, metric screw
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Elektromagnetiniame skirstytuve su M2 centriniu varžtu
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampos lygis	20,4 ... 26,4 V
Nominali darbinė nuolatinė įtampa	24 V
Atsparumas smūgiams	2,4 kV
Apsaugotas nuo poliariškumo pakeitimo	bipolinis
Apsaugotas įžeminimas	Negalimas
Kabelio ilgis	2,5 m
Kabelio priedas	Suitable for energy chains
Laido bandymo sąlygos	Bandyamas pagal užklausimą
Bending radius, flexible cable installation	≥ 29 mm
Kabelio skersmuo	2,9 mm
Kabelio skersmens tolerancija	± 0,1 mm
Kabelio struktūra	2x0,14
Nominalus laidininko skerspjūvis	0,14 mm <sup>2</sup>
Apsaugos klasė	IP65
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-10 ... 50 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	3 - High corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	TPE-U(PU)
Korpuso spalva	Juodas

Savybės	Reikšmė
Material of union nut	Nikeliuotas varis
Material screws	Nerūdijantis plienas
Material electrical contact	Copper alloy, tinned Brass, gold-plated
Material insulation	PP