


Pasyvi ašių kreipiančioji ELFC-KF-32-800

Gaminio numeris: 8062876

FESTO

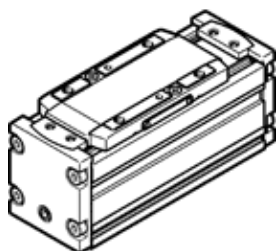

Tech. Duomenys

Savybės	Reikšmė
Darbinė eiga	800 mm
Dydis	32
Eigos rezervas	0 mm
Montavimo pozicija	Bet koks
Kreipiančioji	Cirkuliuojantis guolio kreipiklis
Konstrukcija	Kreipiamoji
Maksimalus pagreitis	250 m/s ²
Maksimalus greitis	1,5 m/s
Budėjimo ciklas	100 %
Atsparumo korozijai klasė CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
RSBP classification to CD-0033	F1a
Švaros klasė	ISO class 7
Apsaugos klasė	IP40
Aplinkos temperatūra	0 ... 50 °C
Inercijos momentas I _y	38E+03 mm ⁴
Inercijos momentas I _z	45E+03 mm ⁴
Maksimali jėga F _y	150 N
Maksimali jėga F _z	300 N
Maksimalus momentas M _x	1,3 Nm
Maksimalus momentas M _y	1,1 Nm
Maksimalus momentas M _z	1,1 Nm
Susukimo inercijos momentas I _t	1,77E+03 mm ⁴
Perstūmimo jėga	2 N
F _y with theoretical service life of 100 km (from a guide perspective only)	552 N
F _z with theoretical service life of 100 km (from a guide perspective only)	1.104 N
M _x with theoretical service life of 100 km (from a guide perspective only)	5 Nm
M _y with theoretical service life of 100 km (from a guide perspective only)	4 Nm
M _z with theoretical service life of 100 km (from a guide perspective only)	4 Nm
Judanti masė	61 g
Papildomas svoris 10mm ilgiui	11 g
Material of end caps	Die-cast aluminium, painted
Material of profile	Anodised wrought aluminium alloy
Informacija	atitinka RoHS
Material cover tape	aukštai legiruotas plienas, nerūdijantis
Material cover	Die-cast aluminium, painted
Material guide slide	Plienas
Material guide rail	Plienas
Material slide	Padengtas aliuminiu