


Maitinimo tinklo filtras CAMF-C6-F-C20-3A

Gaminio numeris: 8088929

★ Kernprogramm

FESTO

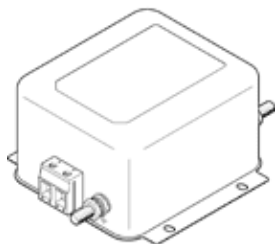

Tech. Duomenys

Savybės	Reikšmė
Atsparumas trumpam jungimui	Ne
Leistina srovės apkrova prie 40°C	20 A
Nominalus AC įtampos lygis	0 ... 250 V
Linijos dažnis	0 ... 400 Hz
Izoliacinė įtampa	1.100 V
Leidimas	ENEC UL - Recognized (OL) c UL - Recognized (OL)
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
Saugojimo temperatūra	-25 ... 100 °C
Apsaugos klasė	IP20
Aplinkos temperatūra	-25 ... 100 °C
Produkto svoris	700 g
Montavimo tipas	Montavimo plokštė, prisukama
Informacija	atitinka RoHS
Montavimo pozicija	Horizontaliai
Electrical connection 1, function	Maitinimas
Electrical connection 1, connection type	Galinė juosta
Electrical connection 1, connection technology	Įsuktas terminalas
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, conductor cross section	4 ... 6 mm ²
Electrical connection 2, function	Maitinimas
Electrical connection 2, connection type	Galinė juosta
Electrical connection 2, connection technology	Įsuktas terminalas
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Electrical connection 2, conductor cross section	4 ... 6 mm ²