


# Pajungimo kabelis NEBS-M12G5-ES-15-LE5

Gaminio numeris: 8097576

FESTO

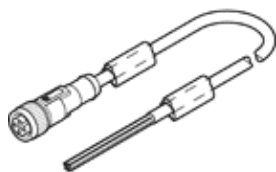

## Tech. Duomenys

Savybės	Reikšmė
Cable identification	with 2x label holders
Produkto svoris	828 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	5
Electrical connection 1, occupied pins/wires	5
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Nominalus DC įtampos lygis	0 ... 60 V
Nominalus AC įtampos lygis	0 ... 48 V
Leistina srovės apkrova prie 40°C	4 A
Atsparumas smūgiams	1,5 kV
Shielding	Taip
Kabelio ilgis	15 m
Kabelio priedas	Suitable for energy chains
Laido bandymo sąlygos	Bandytas pagal užklausimą
Bending radius, fixed cable installation	≥ 26 mm
Bending radius, flexible cable installation	≥ 52 mm
Kabelio skersmuo	5,25 mm
Kabelio skersmens tolerancija	± 0,2 mm
Kabelio struktūra	5x0,34 Ekranuotas
Nominalus laidininko skerspjūvis	0,34 mm <sup>2</sup>
Laido galai	Cut off bluntly
Apsaugos klasė	IP65 IP67
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-40 ... 80 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-25 ... 60 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	Juodas
Material seals	NBR
Material electrical contact	Nickel-plated and gold-plated bronze
Material insulation	PP