


Galinė plokštė CPX-AP-A-EPL

Gaminio numeris: 8112476

FESTO

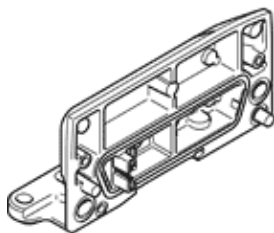

Tech. Duomenys

Savybės	Reikšmė
Matmenys B x L x H	(installation dimensions) 30,4 mm x 117,2 mm x 53,6 mm
Tinklelio matmuo	50,1 mm
Montavimo tipas	Direct mounting via through-holes On H-rail with accessories Montavimo korpuse Via through-hole for M5 screw Via through-hole for M6 screw
Produkto svoris	120 g
Montavimo pozicija	Any, on H-rail: horizontal
Aplinkos temperatūra	-20 ... 50 °C
Note on ambient temperature	Note ambient temperature derating according to IEC 61131-2:2017
Saugojimo temperatūra	-20 ... 70 °C
Sąlyginė oro drėgmė	5 - 95 % nesikondensuojantis
Nominal altitude of use	≤ 2000 m ASL (≥ 79,5 kPa)
Max. installation height	3.500 m
Note on max. installation height	> 2000 m ASL (< 79,5 kPa) Note ambient temperature derating according to IEC 61131-2:2017
Atsparumo korozijai klasė CRC	1 - Low corrosion stress
Atsparumas vibracijoms	Tinkamumo transportui patikra, 2 sunkumo lygio pagal FN 942017-4 ir EN 60068-2-6
Note on vibration resistance	SG1 on H-rail SG2 on direct mounting Tinkamumo transportui patikra, 1 sunkumo lygio pagal FN 942017-4 ir EN 60068-2-6
Atsparumas smūgiams	Shock test with severity level 2 in accordance with FN 942017-5 and EN 60068-2-27
Note on shock resistance	30 g/11 ms to EN 60068-2-27 SG1 on H-rail SG2 on direct mounting Shock test with severity level 1 in accordance with FN 942017-5 and EN 60068-2-27
Saugumo klasė	III
Overvoltage category	II
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno Free of phosphoric acid ester
Material end plate	Die-cast aluminium, coated
Material screws	Steel, nickel-plated Plienas, cinkuotas