


# Ventuza VAS-40-1/4-SI

Cod: 158975

FESTO

Inelul de etansare nu e inclus in completul de livrare.  
produs retras. Livrabil pana in 2012.

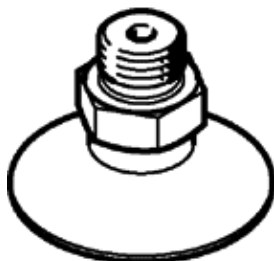

## Fisa tehnica

Caracteristica	valoare
deschidere nominala	4 mm
diametru ventuza	40 mm
diametru efectiv ventuza	32 mm
structura constructiva	racord de vacuum deschis rotund, standard
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
temperatura mediului	-40 ... 200 °C
forta de rupere la 70% vacuum	56 N
greutate produs	13 g
filet de fixare	G1/4
fixarea ventuzei	G 1/4
racord de vacuum	G1/4
duritate Shore	60 +/- 5
informatii referitoare la material pentru fus cu insurubare	aliaj maleabil aluminiu
indicatie material	contine substante cu LABS
informatii referitoare la material pentru ventuza	VMQ (silicon)