


# Mecanism unisens FLSM-12-R

Numar piesa: 164234

FESTO

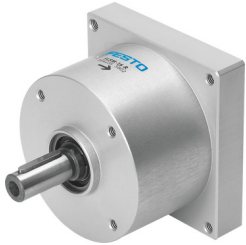

## Fisa de date

Caracteristica	Valoare
Dimensiune	12
Directia de rotire	Rotatie pe dreapta
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-10 °C...60 °C
Cuplu teoretic la 0,6 MPa (6 bari, 87 psi)	1.2 Nm
Greutate produs	300 g
Material carcasa	Aliaj de aluminiu forjat
Material manson	Otel calit
Material arbore	Otel de calire