


Set axial EAMM-A-P3-28D-28A

Numar piesa: 1703478

FESTO

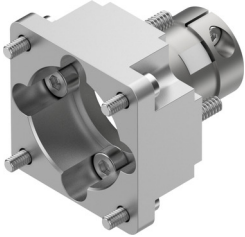

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	0.2 Nm
Greutate produs	30 g
Cod de interfata actuator	P3-28D
Codul interfetei motor In	28A
Cod de interfata carcasa de cuplare	28D
Nota privind materialele	Conform RoHS