


# insula ventile CPA10-VI

Cod: 173520

FESTO

Typ 12, locas 10 mm.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

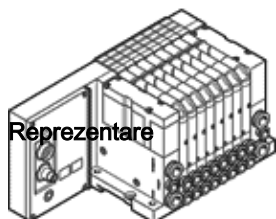

Reprezentare

## Fisa tehnica

~ConfIndependentDatasheet

Caracteristica	valoare
functiune de ventil	2x3/2 deschis/inchis, monostabil 2x3/2 inchis, monostabil 2x3/2 deschis, monostabil 5/2 monostabil 5/2 bistabil 5/3 presurizat 5/3 exhaustat 5/3 inchis
debit nominal normal	300 l/min
presiune de operare	-0,9 ... 10 bar
racordare electrica	AS-Interface racord individual bus de camp Multipol
numarul max. de pozitii de ventile	22
Nr.max.de zone de presiune	11
Sistem electric de I/O	da
temperatura mediului	-5 ... 50 °C
Latime constructie	10 mm
tip de protectie	IP65
aprobare	C-Tick
marimea ramei	10 mm
tip de actionare	electric
tip insula	12
structura constructiva	sertar cu piston
alimentare cu aer pilot	extern intern
structura insulei de ventile	modular si extensibil
afisarea pozitiei de comutare	LED
presiune de comanda	3 ... 8 bar
tensiune nominala de operare DC	24 V
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV
clasa de rezistenta la coroziune KBK	2
temperatura mediului	-5 ... 50 °C