


Flansa oscilanta SNCS-50

Numar piesa: 174399

FESTO

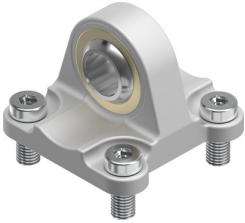

Fisa de date

Caracteristica	Valoare
Dimensiune	50
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...150 °C
Greutate produs	216 g
Nota privind materialele	Conform RoHS
Material fixare	Aluminiu turnat sub presiune
Material rulment articulata	Otel PTFE
Material suruburi	Otel galvanizat