


Flansa oscilanta SNCS-100

Numar piesa: 174402

FESTO

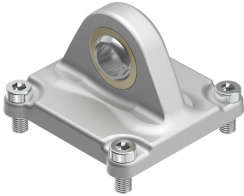

Fisa de date

Caracteristica	Valoare
Dimensiune	100
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...150 °C
Greutate produs	683 g
Nota privind materialele	Conform RoHS
Material fixare	Aliaj de aluminiu forjat
Material rulment articulata	Otel PTFE
Material suruburi	Otel galvanizat